

Quad-Power II



Super HC[®] MN

	B mm	H mm	Ld mm ISO
XPZ	10	8	630 → 3550
XPA	13	10	747 → 4000
XPB	16	13	1250 → 4750
XPC	22	18	2000 → 4750



	B mm	H mm	Ld mm ISO	Ld mm ISO
SPZ	10	8	560 → 3550	560 → 3550
SPA	13	10	732 → 4000	732 → 4500
SPB	16	13	1250 → 4750	1250 → 8000
SPC	22	18	2000 → 4750	2000 → 10600

Hi-Power[®]



 
PoweRated[®]

	B mm	H mm	Ld mm ISO
Z	10	6	470 → 1920
A	13	8	570 → 4610
B	17	11	695 → 4775
C	22	14	1145 → 8405
D	32	19	2570 → 9160




	B	H	OC
3L	3/8"	7/32"	16" → 61"
4L	1/2"	5/16"	17" → 99"
5L	21/32"	3/8"	25" → 99"

Micro-V[®]



Multi-Speed

	H mm	S _g mm	Le mm DIN/ISO
PJ	3.6	2.34	406 → 2489
PL	6.4	4.70	954 → 3696
PM	12.5	9.40	2286 → 9931

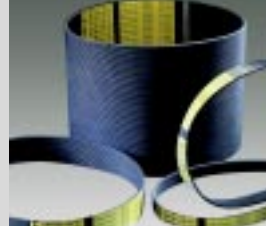

ISO R 1604	B mm	H mm	Lp mm
W16	16.6	5.0	630 → 1000
W20	20.7	6.5	630 → 1250
W25	25.9	8.0	710 → 1600
W31.5	32.6	10.0	900 → 2000
W40	41.5	13.0	1120 → 2500
W50	51.8	16.0	1400 → 3150
W63	65.3	20.0	1800 → 3150


Polyflex[®] JB[™]




	B mm	H mm	e mm	Le mm
5M	5	3.3	5.3	280 → 1500
7M	7	5.3	8.5	490 → 2293
11M	11	7.1	13.2	692 → 2282



 PowerBand[®]



	B mm	H mm	e mm	Le mm RMA
3VX	10	8	10.30	635 → 3555
5VX	16	13	17.50	1270 → 5080
	B mm	H mm	e mm	Ld mm ISO
SPB	16	13	19.00	2120 → 8000
SPC	22	18	25.50	3000 → 5000
9J	10	8	10.30	1250 → 3550
15J	16	13	17.50	1250 → 9000

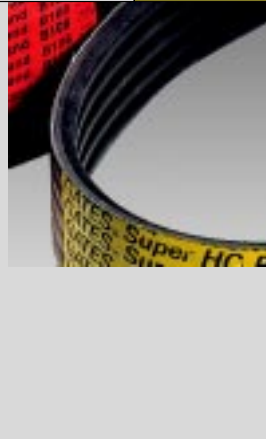

GATES	B mm	H mm	Li mm
13	13.0	6.0	600 → 900
23	23.0	8.0	525 → 1500
28	28.0	9.0	650 → 1600
37	37.0	10.0	800 → 2240
47	47.0	13.0	1000 → 2240

- Ld = datum length - longueur de référence - Richtlänge - referentielengte - longitud de referencia - lunghezza di riferimento - datum längd - datolængde
- Le = effective length - longueur effective - Bezugslänge - effectieve lengte - longitud efectiva - lunghezza effettiva - effektiv längd - effektiv længde
- Lp = pitch length - longueur primitive - Wirklänge - steekcirkellengte - longitud primitiva - lunghezza primitiva - delningslängd - afsnitlængde
- Li = inside length - longueur intérieure - Innenlänge - binnenlengte - longitud interior - lunghezza interna - invändigt längd - indvendigt længde
- OC = outside circumference - circonférence extérieure - Außenlänge - buitenlengte - circunferencia exterior - circonferenza esterna - utvändiga längd - udvendigt længde
- = raw edge - flancs nus - flankenoffen - bandloos - sin forro - fianchi nudi - råkantskuren - fortandet
- = wrapped - enveloppée - ummantelt - ommanteld - con forro - fasciata - vävomsluten - omlagt